

CABIN & COCKPIT ENTRY HARDWARE

MC Compact Cabin Door Lock

A



DOOR THICKNESS RANGE: 19 - 32mm (3/4" - 1-1/4")



The Compact features a simple yet graceful design that works with all swing-door variations. The Compact is designed for Cabin, Stateroom, and Head-door applications.

- All marine-grade materials, including stainless steel and brass for superior corrosion resistance
- Emergency lock override
- Easy installation with rounded forends
- One part number for all swing-door variations

Available Options:

- Finish: Options include: Chrome with/without Brass accent, Satin
- Escutcheon Plates: "Long Island"
- Operation: Universal design fits all door swings
- Accessories
- Doorkeeper: Used to hold door open


For strikers see page 23

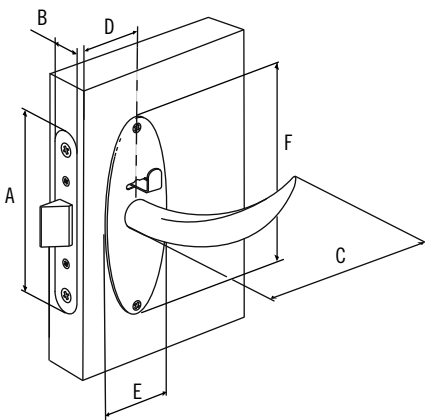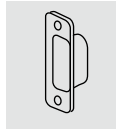

F = Long Island


	Imperial		Metric
	Nominal	Decimal	
A	3 9/16	3.55	90
B	5/8	.63	16
C	3 5/16	3.31	84
D	1 1/4	1.26	32
E	1 3/8	1.38	35
F	3 13/16	3.82	97

Panel Preparation

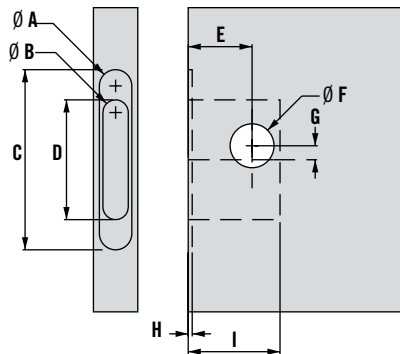

	Compact Long Island		
	Imperial		Metric
	Nominal	Decimal	
A	5/8	.64	16
B	1/2	.50	13
C	3 9/16	3.553	90
D	2 3/8	2.362	60
E	1 17/64	1.26	32
F	7/8	.866	22
G	9/32	.276	7
H	5/64	.079	2
I	1 13/16	1.811	46

How to override a locked Compact door lock from the outside

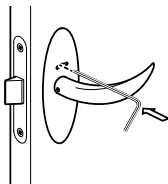

For installation details see opposite page.

COMPACT PART NUMBERS						
Escutcheon Plate Finish	Privacy	Out	In	Left	Right	
Long Island, chrome	X	X	X	X	X	MC-01-120-10
Long Island, chrome, brass accent	X	X	X	X	X	MC-01-120-14
Long Island, satin	X	X	X	X	X	MC-01-120-20
Long Island, cast chrome,	X	X	X	X	X	MC-02-120-10



CABIN & COCKPIT ENTRY HARDWARE Doorkeeper



The Doorkeeper stops and holds doors open. They are designed to work with the McCoy, Offshore and Compact latches (see pages 12-15 and opposite).

- All Marine-grade ABS materials
- Damping/non-vibration feature keeps doors from rattling when held open
- Easy to install

Available Options:


- Color: Available in black or white.

	Imperial		Metric
	Nominal	Decimal	
A	13/16	.787	20
B	1 7/8	1.898	48
C Offshore	1 15/16	1.913	49
C Compact	2 3/16	2.189	56

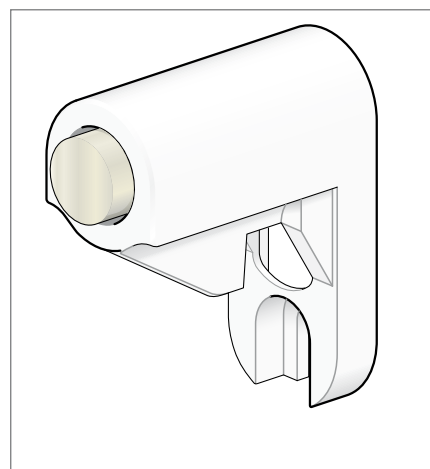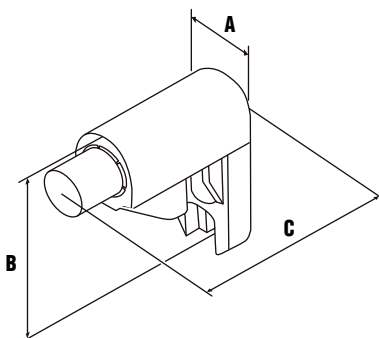


A

Operation

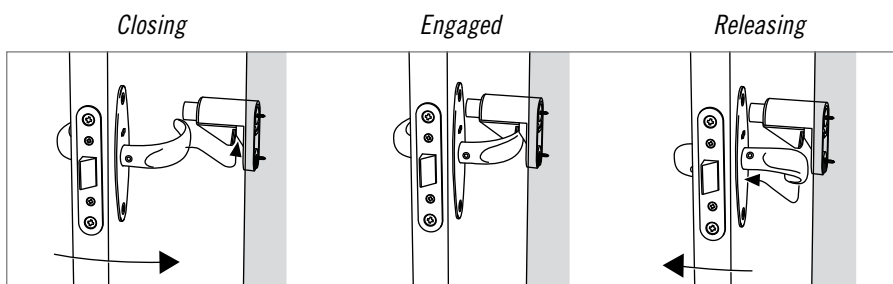

DOORKEEPER PART NUMBERS	
Offshore, Black	MC-91-102-50
Offshore, White	MC-91-102-70
Compact, Black	MC-91-101-50
Compact, White	MC-91-101-70


MC Compact Installation

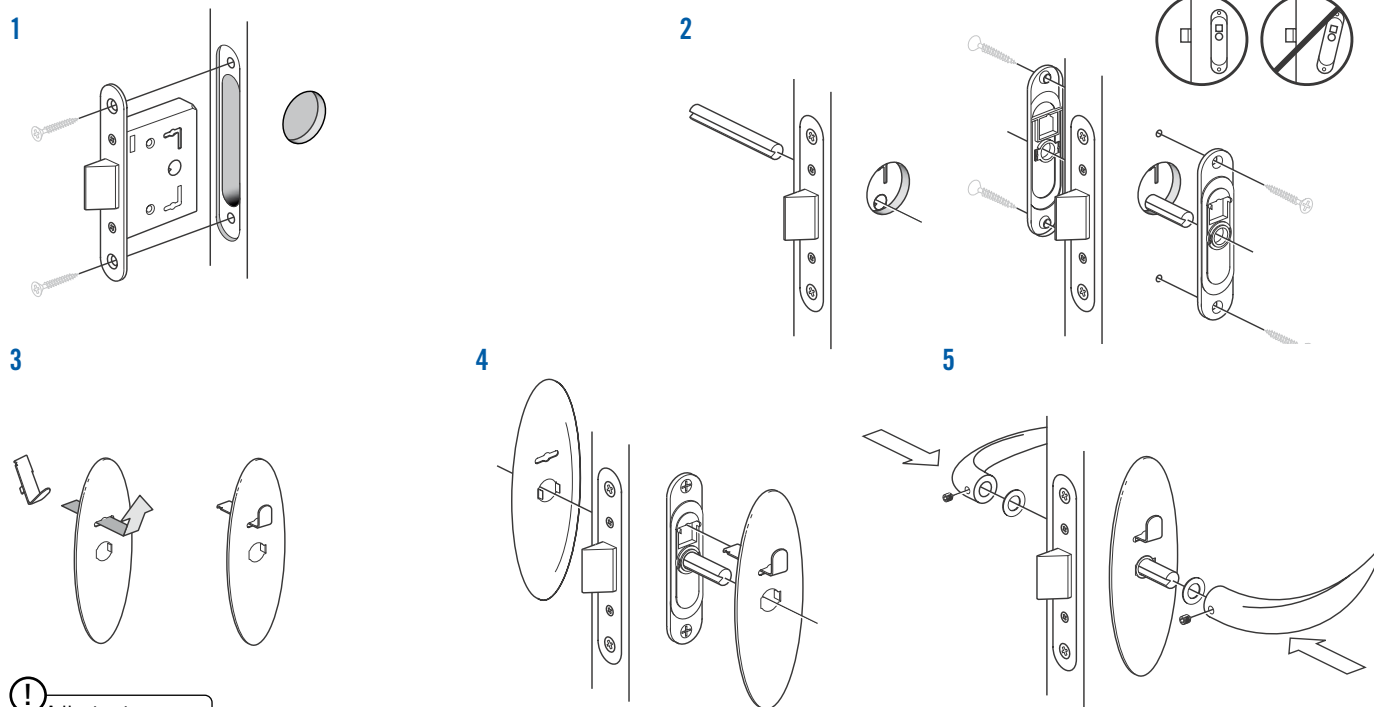


! Adjust set screw to secure handle



MC Pletina Percutora

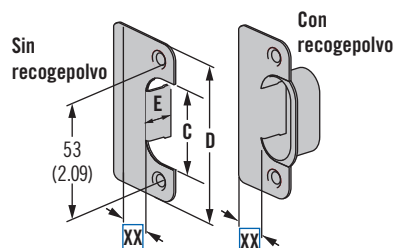

Para encontrar la pletina percutora adecuada para su aplicación, mida la distancia desde la cara de la puerta hasta el borde del pestillo del cierre.

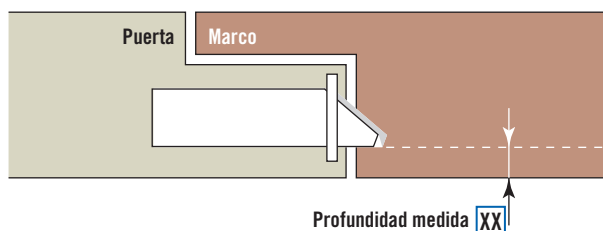

C		D		E	
Métrico	Imperial	Métrico	Imperial	Métrico	Imperial
36	1 (7/16")	68	2 (11/16")	13	1/2


Selección de la Referencia

MC - 90 - Z XX - FF

Z Opción de recoge polvo
 1 Sin recoge polvo
 2 Con recoge polvo

XX Posición
 03 3mm (7/64")
 05 5mm (3/16")
 07 7mm (1/4")
 09 9mm (3/8")
 13 13mm (1/2")
 16 16mm (5/8")
 21 21mm (7/8")

FF Acabado
 10 Latón, niquelado
 24 Acero inoxidable

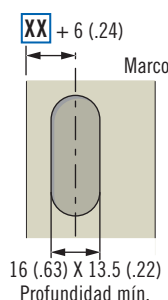


- Disponible en siete tamaños diferentes
- Apta para los cierres de puerta oscilante Offshore, McCoy, Compact y Omni, para numerosas configuraciones de puerta y marco y espesores de puerta
- La lengüeta de la Pletina Percutora evita el desgaste por la vibración de la embarcación
- El recoge polvo opcional oculta el serrín en la hendidura del pestillo y brinda un elegante acabado al borde del marco



www.southco.com/MC

MC Pletina Percutora Whale

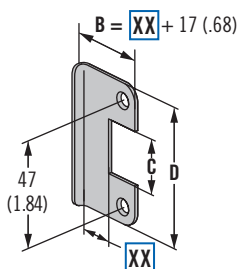

C		D	
Métrico	Imperial	Métrico	Imperial
60	2 (3/8")	22	7/8

- Apta para los cierres de puerta oscilante Offshore, McCoy, Compact.
- Instalación rápida y sencilla

Selección de la Referencia

MC - 90 - 3 - XX - FF

XX Posición
 03 3mm (7/64")
 05 5mm (3/16")
 07 7mm (1/4")
 09 9mm (3/8")
 13 13mm (1/2")
 16 16mm (5/8")
 21 21mm (7/8")

FF Acabado
 10 Latón, niquelado
 40 Latón

